


Cell Biology

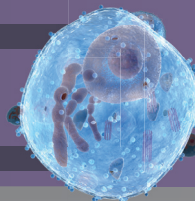

Please use this data sheet to find a selection of products for the different applications within Cell Biology. For a full listing of our Cell Biology Cell Culture products, please visit our dedicated Web sites:

www.fishersci.com/lifescience/cell_biology

www.fishersci.com/lifescience/cellculture

We also invite you to reference the following related publications from Fisher Scientific:

Cell Culture Catalog: BN1212075

Fisherbrand Cell Culture Consumables: BN0408091

Cat. No.	Description	List Price	QTY.
Cell Culture - Reagents			
SH30027FS	Thermo Scientific HyClone Classical Liquid Media: RPMI 1640	79.03	PK
SH30243FS	Thermo Scientific HyClone Classical Liquid Media DMEM, High Glucose	79.03	PK
SH3002201	Thermo Scientific HyClone Classical Liquid Media DMEM, High Glucose, without Sodium Pyruvate	13.44	EA
SH30860LS	Thermo Scientific HyClone SFMTransfx-293 Media	339.93	EA
SH3035902	Thermo Scientific HyClone PF-CHO, with L-Glutamine	52.00	EA
SH3027802	Thermo Scientific HyClone SFX-Insect	49.51	EA
SH3007003	Thermo Scientific HyClone Fetal Bovine Serum, U.S. Origin	325.50	EA
SH3007103	Thermo Scientific HyClone Characterized Fetal Bovine Serum, U.S. Origin	298.20	EA
SH3091003	Thermo Scientific HyClone USDA Tested Serum	204.75	EA
SH3039603	Thermo Scientific HyClone Characterized Fetal Bovine Serum, Canadian Origin	152.50	EA
SH3002802	Thermo Scientific HyClone Dulbecco's Phosphate Buffered Saline (DPBS)	10.00	EA
SH3025601	Thermo Scientific HyClone Phosphate Buffered Saline (PBS)	10.00	EA
SH30221LS	Thermo Scientific HyClone WFI Quality Water	95.49	PK
SV30010	Thermo Scientific HyClone Penicillin-Streptomycin Solution	15.10	EA
SV3006901	Thermo Scientific HyClone Antibiotics, G418 Sulfate Solution	129.61	EA
SH3004201	Thermo Scientific HyClone Trypsin	9.45	EA
CB40230	BD Matrigel Basement Membrane Matrix, Growth Factor Reduced	320.36	EA
CB40234	BD Matrigel Basement Membrane Matrix	266.37	EA
CB40008A	BD Fibronectin, Human	314.54	EA
PRG5381	Promega Vitronectin, Human	307.60	EA
45001750	GE Healthcare Ficoll-Paque PLUS	485.00	PK
Cell Culture - Consumables			
08100240	Fisherbrand Cell Lifters	162.51	CS
08100241	Fisherbrand Cell Scrapers, Small	235.54	CS
22363547	Fisherbrand Cell Strainers	99.59	CS
055395	Fisherbrand Easy Reader Plastic Centrifuge Tubes, 15mL, Polypropylene	188.43	CS
055398	Fisherbrand Easy Reader Plastic Centrifuge Tubes, 50mL, Polypropylene	254.32	CS
1367811	Fisherbrand Polystyrene Disposable Serological Pipets with Magnifier Stripe, 25mL	182.99	CS
1367811D	Fisherbrand Polystyrene Disposable Serological Pipets with Magnifier Stripe, 5mL	77.21	CS
FB800250	Fisherbrand Reusable Glass Media Bottles with Cap, 250mL	84.27	CS
FB800500	Fisherbrand Reusable Glass Media Bottles with Cap, 500mL	100.75	CS
12565348	Thermo Scientific Nunc Treated EasyFlasks, with Vent/Close Caps	307.58	CS
1256637	Thermo Scientific Nunc MicroWell 96-Well Optical-Bottom Plates	1153.32	CS
12565261	Thermo Scientific Nunc Immuno 96-Well Plates	219.44	CS
12567105	Thermo Scientific Nunc Low Cell Binding Microplates	111.99	CS
12565165	Thermo Scientific Nunc Nunclon Δ Multidishes, Round Wells	325.52	CS
12565494	Thermo Scientific Nunc Nunclon Δ Multidishes, Rectangular Wells	430.18	CS
12565900	Thermo Scientific Nunc Multidishes, Poly-D-Lysine Surface	174.16	CS
12565907	Thermo Scientific Nunc Multidishes, Collagen I Surface	174.16	CS
08772168	BD PureCoat Carboxyl Surface Dishes	35.00	CS

Cat. No.	Description	List Price	QTY.
Cell Culture - Consumables (continued)			
08772173	BD PureCoat Culture Dishes	107.00	CS
08774263	BD BioCoat Poly-D-Lysine Plug-Seal Cap Flasks	302.28	CS
08774267	BD BioCoat Collagen I, Rat Tail Plug-Seal Cap Flasks, T-150cm ²	630.74	CS
08774302	BD BioCoat Gelatin Culture Flasks	58.46	CS
0877413	BD BioCoat Collagen I, Rat Tail Plug-Seal Cap Flasks, T-25cm ²	98.59	CS
0877468	BD BioCoat Fibronectin, Human, Culture Flasks	175.40	CS
0877493	BD BioCoat Laminin, Mouse Culture Flasks	207.00	CS
0720190	Corning CellSTACK Culture Chambers	383.25	CS
08757210	Corning Polystyrene Roller Bottles	865.43	CS
07201153	Corning Disposable Spinner Flask with Top Cap and Angled Sidearms	1061.70	CS
Cell Culture Equipment			
13898230	Thermo Scientific Revco Ultima PLUS HD Ultra-low Upright Freezer	18,260.00	EA
13989103	Thermo Scientific Revco Elite Series Ultra-low Upright Freezer	10,075.00	EA
15474340	Thermo Scientific Forma 900 Series Ultra-low Upright Freezer	16,154.00	EA
13990242	Thermo Scientific Revco Ultima II Ultra-low Chest Freezer	8906.00	EA
13989109	Thermo Scientific Revco Elite Ultra-low Chest Freezer	7007.00	EA
15474349	Thermo Scientific Forma 8600 Series Ultra-low Chest Freezer	12,290.00	EA
1427836	Fisher Scientific Isotemp Ultra-low Undercounter Freezer	10,065.00	EA
13261300	Thermo Scientific 1300 Series Type A2 Class II, Biological Safety Cabinet	8023.00	EA
13998000	Thermo Scientific Herasafe KS Class II, Type A2 Biological Safety Cabinet	10,000.00	EA
15497009	Thermo Scientific Napco 8000 Direct-Heat CO ₂ Incubator	6426.00	EA
13998090	Thermo Scientific Forma Steri-Cult CO ₂ Incubator	12,868.00	EA
75004506	Thermo Scientific Sorvall Legend XT Centrifuge Series	7181.00	EA
75004510	Thermo Scientific Sorvall ST40 Centrifuge Series	6150.00	EA
Cryopreservation			
12567500	Fisherbrand Internally Threaded Cryogenic Storage Vials 1.2mL	46.47	PK
1050025	Fisherbrand Externally Threaded Cryogenic Storage Vials 1.2mL	46.97	PK
12567507	Fisherbrand Color Coders for Internally Threaded Cryogenic Storage Vials - Red	17.20	CS
1050034	Fisherbrand Color Coders for Externally Threaded Cryogenic Storage Vials - Red	19.46	CS
1535050	Thermo Scientific Nalgene "Mr. Frosty" Freezing Container	74.45	CS
03395479	Fisherbrand Upright Metal Freezer Rack 2 3x3	66.28	EA
1167654	Thermo Scientific Locator Plus Rack & Box System	5990.00	EA
TF7401	Thermo Scientific CryoPlus Storage System	8900.00	EA
1167590	Thermo Scientific Bio-Cane Cane and Canister System	1241.15	EA
11675900	Thermo Scientific Arctic Express Dual Storage Systems	1695.00	EA
Microscopy			
12575252	Fisher Scientific Micromaster Inverted Microscope	6544.22	EA
12070441	Carl Zeiss Axiovert 40 CFL	17,650.00	EA
12563461	AMG EVOS fl	30,200.00	EA
Fixation			
22046339	Thermo Scientific Richard-Allan Cal-Rite Decalcifying/Fixation Solution	115.70	EA
22110621	Thermo Scientific Richard-Allan Scientific Bouin's Fluid	368.53	EA
Staining			
22110646	Thermo Scientific Richard-Allan Mucicarmine Kit	612.57	EA
CS434D	Fisher Scientific SureStain Stains	127.29	EA
Immunohistochemistry			
034481	Fisherbrand Color Coded ABS Plastic Boxes	24.23	EA
154640	Fisher Scientific TissuePrep Circular Flotation Bath	620.34	EA
125525	Fisherbrand Frosted Microslides	63.07	GR
15200403A	Fisherbrand TRUFLOW Tissue and Biopsy Cassettes	407.15	CS

Cat. No.	Description	List Price	QTY.
Immunohistochemistry (continued)			
AS7202D	Thermo Scientific Lab Vision AutoStainer	87,200.00	EA
22050856	Thermo Scientific Richard-Allan Microm HM 450 Sliding Microtome	13,442.37	EA
23900669	Thermo Scientific Richard-Allan Microm HM 340E Automated Rotary Microtome	11,446.52	EA
OB10001	SouthernBiotech Fluoromount G Slide Mounting Medium	50.75	EA
Fluorescent Imaging			
PI33005	Thermo Scientific Pierce Amine-Reactive Probes	100.41	PK
PI53034	Thermo Scientific DyLight Antibody Labeling Kits	300.17	EA
PI46421	Thermo Scientific DyLight Reactive Dyes	215.81	EA
PRG8241	Promega HaloTag Interchangeable Labeling Technology	158.01	EA
45000693	GE Healthcare Amersham CyDye Value Packs (bis-Reactive NHS Ester)	851.00	EA
45001288	GE Healthcare Amersham CyDye Post-Labeling Reactive Dye Packs	182.00	EA
05728308	Kodak X-SIGHT Nanosphere Conjugates from Carestream Health	282.32	EA
Transfection			
PRE2311	Promega FuGENE HD Transfection Reagent	355.00	EA
PRE2431	Promega TransFAST Transfection Reagent	280.43	EA
PRA3600	Promega pGEM-T Vector System I pGEM-T	119.83	EA
PRE1200	Promega ProFection Mammalian Transfection System	137.70	EA
MIR5400	Mirus Bio TransIT-2020 Reagent	360.00	EA
MIR2000	Mirus Bio TransIT-Express Transfection Reagent	305.60	EA
MIR2300	Mirus Bio TransIT-LT1 Transfection Reagent	274.91	EA
MIR2400	Mirus Bio TransIT-LT2 Transfection Reagent	278.03	EA
PI89850	Thermo Scientific Pierce Pro-Ject Protein Transfection Kit	283.55	EA
T202015	GenePORTER 2 Transfection Reagent	403.61	EA
T901015	Genlantis TrojanPORTER Transfection Reagent	397.82	EA
BP502401	Genlantis BioPORTER Protein Delivery Reagents and Kits	283.17	EA
Protein Expression			
14379521	Thermo Scientific SuperChip AdvaNCe-2	415.78	CS
PRE1200	Promega ProFection Mammalian Transfection System	137.70	EA
PRL1020	Promega <i>E. coli</i> S30 Extract System for Circular DNA	377.12	EA
FP2401100	5 PRIME <i>E. coli</i> HY Kits	493.23	EA
BP502424	Genlantis BioPORTER Protein Delivery Kits	346.68	EA
Gene Knockdown			
T201001	Thermo Scientific Dharmacon DharmaFECT Duo Transfection Reagents	93.01	EA
T200101	Thermo Scientific Dharmacon DharmaFECT siRNA Transfection Reagents	90.75	EA
PRC8790	Promega GeneClip U1 Hairpin Cloning Systems	368.19	EA
PRC8021	Promega psiCHECK Vectors	339.19	EA
MIR8610	Mirus Label IT miRNA Labeling Kits	301.91	EA
MIR2150	Mirus TransIT-TKO siRNA Transfection Reagent	411.31	EA
Cell-Based Assays			
PRG7571	Promega CellTiter-Glo Luminescent Cell Viability Assay Kit	410.00	EA
PRG8091	Promega Caspase-Glo 3/7 Assay Kit	362.00	EA
PRG3580	Promega CellTiter 96 Aqueous One Solution Cell Proliferation Assay (MTS)	255.65	EA
PRG7791	Promega Apo-ONE Homogeneous Caspase-3/7 Assay Kit	1858.95	EA
PRG1780	Promega Cyto Tox 96 Nonradioactive Cytotoxicity Assay	262.89	EA
PRG8081	Promega CellTiter-Blue Cell Viability Assay	285.83	EA
PRG3250	Promega DeadEnd Fluorometric TUNEL System	484.04	EA
PRG6082	Promega CellTiter-Fluor Cell Viability Assay	653.82	EA
PRG7341	Promega Anti-PARP p85 Fragment, Polyclonal	345.51	EA

Cat. No.	Description	List Price	QTY.
Cell-Based Assays (continued)			
8402902	Thermo Scientific Cellomics Phospho H2AX Detection Kit	716.31	EA
K0200011	Thermo Scientific Cellomics Cell Viability HCS Reagent Kit	486.95	EA
K0700011	Thermo Scientific Cellomics Neurite Outgrowth HitKit Reagent Kit	587.97	EA
Flow Cytometry			
09980021	Thermo Scientific Nanosphere 3000 Series Size Standards 100nm	270.51	EA
09980049	Thermo Scientific Duke Nanosphere 4000 Series Monosized Particles 5.0um	338.63	EA
09980054	Thermo Scientific Duke Nanosphere 4000 Series Monosized Particles 10um	338.63	EA
09980065	Thermo Scientific Duke Nanosphere 4000 Series Monosized Particles 100um	338.63	EA
09980236	Thermo Scientific PHARM-TROL Count Precision Size Standards 15um	641.00	PK
BDB560770	BD Biosciences anti-CD3, Clone SP34-2, Horizon V500	395.00	EA
BDB560774	BD Biosciences anti-CD8, Clone RTA-T8, Horizon V500	395.00	EA
BDB560771	BD Biosciences anti-CD3, Clone 500A2, Horizon V500	330.00	EA
BDB560787	BD Biosciences anti-IgG, Clone X40, Horizon V500	330.00	EA
BDB560785	BD Biosciences anti-IgG2, Clone B81-3, Horizon V500	330.00	EA
BDB560786	BD Biosciences anti-IgG2, Clone R35-95, Horizon V500	330.00	EA
Lab Essentials			
FB100250	Fisherbrand Glass Beakers	50.71	PK
FB500500	Fisherbrand Erlenmeyer Flasks	38.87	PK
1495925C	Fisherbrand Reusable Glass Tubes	391.59	CS
055398	Fisherbrand Centrifuge Tubes	254.32	CS
05408120	Fisherbrand Microcentrifuge Tubes	53.80	PK
BBV125	Fisherbrand Shaker Flasks	164.09	CS
08647700	Fisherbrand Wash Bottles	44.35	PK
1371120	Fisherbrand Transfer Pipets	88.79	PK
02911960	Fisherbrand Plastic Containers	59.17	CS
12565638	Fisherbrand Carboy	159.73	EA

Trademarks of Our Suppliers: 5 PRIME, μ Array, AdvanCe, Allure, Amersham, Apo-ONE, Arctic Express, Axiovert, BD, Bel-Art, Bio-Cane, BioCoat, BioPORTER, B-PER, Carl Zeiss, Caspase-Glo, Catch and Release, Cellomics, CellSTACK, CellTiter 96, CellTiter-Blue, CheckMate, Corning, Costar, COUNT-CAL, CryoPlus, CyDye, DeadEnd, Dharmacon, DharmaFECT, DyLight, EasyCast, EasYflask, Easy Reader, ECL, ECL Plex, ECL Plus, EVOS, EZ-Label, EZY-CAL, Falcon, FastPlasmid, Ficoll-Paque, Flexi, Fluoromount-G, FluoroNunc, FluoroTect, Forma, GE, GelCode, GeneClip, GenePORTER, Genlantis, GoScript, HaloTag, HERAsafe, HiTrap, Hybond, HyClone, HyperSep, Hypersil GOLD, ImProm-II, InVitro, Kodak, Lab Vision, Label IT, Legend, Lonza, LumiNunc, Marligen, Mastercycler, MasterMix, Matrigel, MaxiSorp, Megaprime, MemCode, MicroWell, Millicent, Mirus, Montage, M-PER, MultiScreen HTS, NE-PER, Nunc, Nunc-Immuno, Nunclon, Percoll, Perfectprep, PerfectPure, pGEM, PHARM-TROL, Plexor, PowerPlex, ProbeQuant, ProFection, ProFound, Promega, ProteaseMAX, ProteoSeek, psiCHECK, PureCoat, PureYield, Pyrex, QuikEase, Ready-to-Go, Red Hot, Revco, Richard-Allan, RNasin, SeaKem, SeqWright, SFX-Insect, Signet, SilverSNAP, SmartPlex, SNAP i.d., SORVALL, SouthernBiotech, SuperChip, SwellGel, Takara, Thermo-Fast, Thermo Scientific, Thermowell, TransIT-TKO, TRUFLOW, twin.tec, Ultima, UltraGAPS, Wizard, X-Sight, Y-PER

Trademarks of Fisher Scientific: Easy Reader, EZ-Run, Fisherbrand, Isotemp, Micromaster, Optima, SureStain, TissuePrep



Fisher Scientific

Part of Thermo Fisher Scientific

For customer service, call 1-800-766-7000.
 To fax an order, use 1-800-926-1166.
 To order online: www.fishersci.com

©2010 Thermo Fisher Scientific Inc. All rights reserved.

Litho in U.S.A. 09_2426 KE/SL 5M-IW-03/10