


Fits in. Stands out.

Take advantage of these special offers

Packages designed around your applications.

Order your centrifuge, rotor and accessories with 1 part number.

- Cell culture
- Microplate and molecular biology
- Multi-application

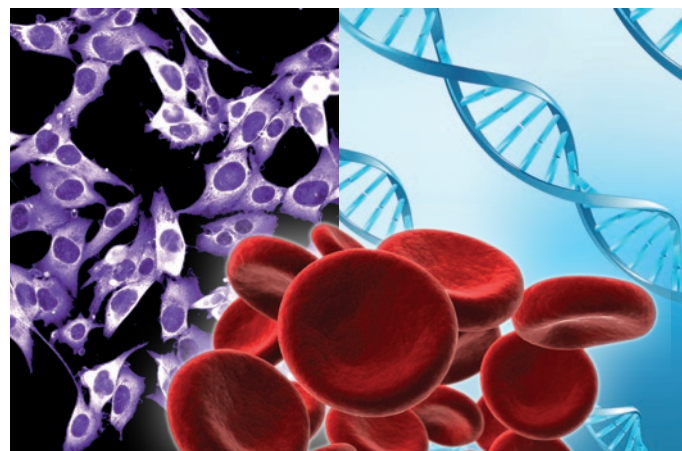

Thermo Scientific™ Sorvall™ benchtop centrifuges

Fits in.

- To your space, with compact designs
- To your processes and protocols, with complete application-focused packages
- To your future, with a 5-year centrifuge warranty¹ on select packages

¹ Restrictions apply. Please see thermofisher.com/spinitwarranty for complete warranty offer and coverage details.

² Biocontainment certification by Public Health England, Porton Down, UK.

Stands out.

Featuring innovative Thermo Scientific™ technologies:

- Secure, push-button rotor exchange in as little as 3 seconds with Auto-Lock™ rotor exchange
- Outstanding ergonomics and performance with Fiberlite™ carbon fiber rotors
- One-handed, certified² sample protection by ClickSeal™ biocontainment lids
- Plus, powerful performance with swing-out capacities up to 4 L and fixed angle rotor speeds over 30,000 x g

5-YEAR
CENTRIFUGE
WARRANTY¹
included with
select packages

Cell culture packages





Swing-out packages developed for 50 and 15 mL conical tubes. Excellent for cell culture and general life science applications.

Choose for:

- High performance—spin tubes up to 4,816 x g for fast separations
- High capacities from 4 to 40 x 50 mL tubes and 20 to 96 x 15 mL tubes for high throughput
- ClickSeal biocontainment lids designed for user and sample contamination protection



- Optimized deceleration rates for delicate eukaryotic cell pellets, maintaining high yields

Centrifuge	Cat. No.	Package includes
4 L high performance and high throughput 40 x 50 mL tubes up to 4,200 rpm/4,122 x g (refrigerated) or up to 3,800 rpm/3,374 x g (ventilated)		<div style="background-color: red; color: white; padding: 5px; display: inline-block;">5-YEAR CENTRIFUGE WARRANTY¹</div> <ul style="list-style-type: none"> • TX-1000 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-1000 aerodynamic buckets (set of 4) – TX-1000 ClickSeal biocontainment lids (set of 4) – Adapters 40 x 50 mL conical – Adapters 96 x 15 mL conical 
Sorvall Legend XFR floor-standing refrigerated centrifuge	75397406	
Sorvall Legend XF floor-standing ventilated centrifuge	75337406	
Sorvall Legend XTR refrigerated centrifuge	75217406	
Sorvall Legend XT ventilated centrifuge	75067406	
3 L high performance 28 x 50 mL tubes up to 4,700 rpm/4,816 x g		<div style="background-color: red; color: white; padding: 5px; display: inline-block;">5-YEAR CENTRIFUGE WARRANTY¹</div> <ul style="list-style-type: none"> • TX-750 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-750 buckets (set of 4) – TX-750 ClickSeal biocontainment lids (set of 4) – Adapters 28 x 50 mL conical – Adapters 56 x 15 mL conical 
Sorvall Legend XTR refrigerated centrifuge	75213839	
Sorvall Legend XT ventilated centrifuge	75063839	
1.6 L high performance 16 x 50 mL tubes up to 5,000 rpm/4,696 x g		<div style="background-color: red; color: white; padding: 5px; display: inline-block;">5-YEAR CENTRIFUGE WARRANTY¹</div> <ul style="list-style-type: none"> • TX-400 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-400 buckets (set of 4) – TX-400 ClickSeal biocontainment lids (set of 4) – Adapters 16 x 50 mL conical – Adapters 36 x 15 mL conical 
Sorvall Legend X1R refrigerated centrifuge	75618382	
Sorvall Legend X1 ventilated centrifuge	75218382	
580 mL high performance 8 x 50 mL tubes up to 4,500 rpm/3,260 x g		<div style="background-color: red; color: white; padding: 5px; display: inline-block;">2-YEAR CENTRIFUGE WARRANTY³</div> <ul style="list-style-type: none"> • TX-150 rotor <ul style="list-style-type: none"> – TX-150 oval buckets (set of 4) – Adapters 8 x 15 mL conical 
Sorvall ST 8R refrigerated centrifuge	75230395	
Sorvall ST 8 ventilated centrifuge	75200395	

¹ Restrictions apply. Please see thermofisher.com/spinitwarranty for complete warranty offer and coverage details.

³ Subject to Thermo Fisher Scientific's standard limited warranty. See thermofisher.com or your sales representative for details.





Multi-application packages

Multi-rotor packages developed for multi-application environments, meeting your lab's evolving needs with outstanding flexibility and performance.

Choose for:

- Auto-Lock rotor exchange allows you to safely change rotors and applications in as little as 3 seconds with just a push of a button
- High-speed performance for quick spins and fast results
- Large selection of optional rotors and accessories to accommodate a wide variety of tubes
- Fixed angle flexibility with a choice of standard aluminum or high-performance, high-capacity Fiberlite carbon fiber rotors



Centrifuge	Cat. No.	Package includes
4 L high throughput swing-out and high-capacity fixed angle 40 x 50 mL tubes up to 4,200 rpm/4,122 x g (refrigerated) or 3,800 rpm/3,374 x g (ventilated), and 6 x 250 mL tubes up to 10,000 rpm/15,317 x g		5-YEAR CENTRIFUGE WARRANTY¹  <ul style="list-style-type: none"> • TX-1000 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-1000 aerodynamic buckets (set of 4) – TX-1000 ClickSeal biocontainment lids (set of 4) – Adapters 40 x 50 mL conical – Adapters 96 x 15 mL conical • Fiberlite F14-6x250 LE rotor
Sorvall Legend XFR floor-standing refrigerated centrifuge	75391762	
Sorvall Legend XF floor-standing ventilated centrifuge	75331762	
Sorvall Legend XTR refrigerated centrifuge	75211762	
Sorvall Legend XT ventilated centrifuge	75061762	
3 L high performance swing-out and mid-capacity fixed angle 28 x 50 mL tubes up to 4,700 rpm/4,816 x g, and 6 x 100 mL tubes up to 14,500 rpm/24,446 x g		5-YEAR CENTRIFUGE WARRANTY¹  <ul style="list-style-type: none"> • TX-750 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-750 buckets (set of 4) – TX-750 ClickSeal biocontainment lids (set of 4) – Adapters 28 x 50 mL conical – Adapters 56 x 15 mL conical • Fiberlite F15-8x50cy rotor
Sorvall Legend XTR refrigerated centrifuge	75063963	
Sorvall Legend XT ventilated centrifuge	75213963	
1.6 L high performance and flexibility 16 x 50 mL tubes up to 5,000 rpm/4,696 x g		5-YEAR CENTRIFUGE WARRANTY¹  <ul style="list-style-type: none"> • TX-400 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-400 buckets (set of 4) – TX-400 ClickSeal biocontainment lids (set of 4) – Adapters 16 x 50 mL conical – Adapters 36 x 15 mL conical • HIGHConic II 6 x 100 rotor <ul style="list-style-type: none"> – Adapters 6 x 50 mL conical • M-20 6 x Microplate rotor • MicroClick 30 x 2 rotor
Sorvall Legend X1R refrigerated centrifuge	75612024	
Sorvall Legend X1 ventilated centrifuge	75212024	
580 mL high performance and flexibility 4 x 50 mL tubes up to 4,500 rpm/3,260 x g		2-YEAR CENTRIFUGE WARRANTY³  <ul style="list-style-type: none"> • TX-150 rotor <ul style="list-style-type: none"> – TX-150 buckets (set of 4) – TX-150 ClickSeal biocontainment lids (set of 4) – Adapters 4 x 50 mL conical – Adapters 8 x 15 mL conical • HIGHConic III 6 x 50 rotor • M10 4 x Microplate rotor • MicroClick 24 x 2 rotor
Sorvall ST 8R refrigerated centrifuge	75230906	
Sorvall ST 8 ventilated centrifuge	75200906	

¹ Restrictions apply. Please see thermofisher.com/spinitwarranty for complete warranty offer and coverage details.


³ Subject to Thermo Fisher Scientific's standard limited warranty. See thermofisher.com or your sales representative for details.

Microplate and molecular biology packages






Supporting a wide variety of micro-volume solutions with small footprints, high capacities and quiet operation.

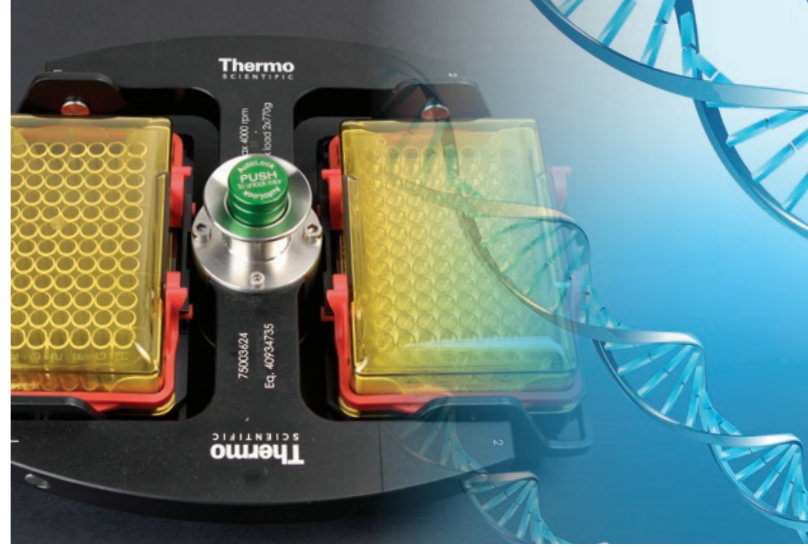Choose for:

- Microplate rotors with capacities from 4 to 24 standard microplates, many with optional certified² biocontainment
- ClickSeal biocontainment lids allow access to samples in seconds
- MicroClick rotors feature extended necks, designed specifically for nucleic acid purification kits



- High speed performance up to 30,279 x g for fast spins and outstanding separations

Centrifuge	Cat. No.	Package includes
High throughput microplate		
24 standard microplates up to 4,200 rpm/4,122 x g (refrigerated) or 3,800 rpm/3,374 x g (ventilated)		
Sorvall ST 40R refrigerated centrifuge	75251703	<div style="background-color: red; color: white; padding: 5px; display: inline-block;">5-YEAR CENTRIFUGE WARRANTY¹</div> <ul style="list-style-type: none"> • TX-1000 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-1000 aerodynamic buckets (set of 4) – TX-1000 ClickSeal biocontainment lids (set of 4) – Microplate adapters (set of 4) 
Sorvall ST 40 ventilated centrifuge	75101703	
High performance microplate		
16 standard microplates up to 4,700 rpm/4,816 x g		
Sorvall XTR refrigerated centrifuge	75210817	<div style="background-color: red; color: white; padding: 5px; display: inline-block;">5-YEAR CENTRIFUGE WARRANTY¹</div> <ul style="list-style-type: none"> • TX-750 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-750 Microplate buckets (set of 4) 
Sorvall XT ventilated centrifuge	75060817	
Standard microplate		
4 standard microplates up to 4,400 rpm/2,576 x g		
Sorvall ST 8R refrigerated centrifuge	75230623	<div style="background-color: red; color: white; padding: 5px; display: inline-block;">2-YEAR CENTRIFUGE WARRANTY³</div> <ul style="list-style-type: none"> • M10 rotor 
Sorvall ST 8 ventilated centrifuge	75200623	
1.6 L high throughput molecular biology		
16 x 50 mL tubes up to 5,000 rpm/4,696 x g and 30 microtubes up to 14,000 rpm/21,693 x g		
Sorvall Legend X1R refrigerated centrifuge	75618119	<div style="background-color: red; color: white; padding: 5px; display: inline-block;">5-YEAR CENTRIFUGE WARRANTY¹</div> <ul style="list-style-type: none"> • TX-400 rotor with Slide Coat anti-friction finish <ul style="list-style-type: none"> – TX-400 buckets (set of 4) – TX-400 ClickSeal biocontainment lids (set of 4) – Adapters 16 x 50 mL conical – Adapters 36 x 15 mL conical • MicroClick 30 x 2 rotor (prep kit compatible) 
Sorvall Legend X1 ventilated centrifuge	75218119	
580 mL high performance molecular biology		
4 x 50 mL tubes up to 4,500 rpm/3,260 x g and 24 microtubes up to 17,850 rpm/30,279 x g		
Sorvall ST 8R refrigerated centrifuge	75230115	<div style="background-color: red; color: white; padding: 5px; display: inline-block;">2-YEAR CENTRIFUGE WARRANTY³</div> <ul style="list-style-type: none"> • TX-150 rotor <ul style="list-style-type: none"> – TX-150 buckets (set of 4) – TX-150 ClickSeal biocontainment lids (set of 4) – Adapters 4 x 50 mL conical – Adapters 8 x 15 mL conical • MicroClick 24 x 2 rotor 
Sorvall ST 8 ventilated centrifuge	75200115	

¹ Restrictions apply. Please see thermofisher.com/spinitwarranty for complete warranty offer and coverage details.

² Biocontainment certification by Public Health England, Porton Down, UK.

³ Subject to Thermo Fisher Scientific's standard limited warranty. See thermofisher.com or your sales representative for details.

Increase your package flexibility even further with add-ons

After you choose your application-focused package, simply select from complementary Thermo Scientific products to further enhance your lab's processing capabilities.



Thermo Scientific™ mySPIN™ 12 and 6 mini centrifuges

Add-on rotors and adapters

Thermo Scientific rotor/adaptor	Cat. No.	Corresponding centrifuge/maximum RCF				
		Sorvall Legend XT	Sorvall ST 40	Sorvall Legend X1	Sorvall ST 16	Sorvall ST 8
Fiberlite F14-6x250 LE rotor	75773662	15,317 x g				
Fiberlite F13-14x50cy rotor	75773661	14,636 x g		12,359 x g		
Fiberlite F15-6x100y rotor	75773698	24,652 x g	18,516 x g	24,652 x g	18,516 x g	
Fiberlite F15-8x50cy rotor	75773663	24,446 x g		22,789 x g		
HIGHConic II rotor	75773620	15,090 x g	15,090 x g	15,090 x g	15,090 x g	
Microliter 48 x 2 rotor	75773602	25,314 x g	25,314 x g	25,314 x g	25,314 x g	
Microliter 30 x 2 rotor	75773652	25,830 x g	25,830 x g	25,830 x g	25,830 x g	
MicroClick 30 x 2 rotor (prep kit compatible)	75775719	21,693 x g	21,693 x g	21,693 x g	21,693 x g	21,693 x g
TX-1000 microplate adapters ⁴	75777303	>3,374 x g	>3,374 x g			
M-20 rotor with standard microplate carriers	75773624	2,272 x g	2,272 x g	2,272 x g	2,272 x g	
Sealed microplate carriers for M-20 rotor ⁴	75773625	2,272 x g	2,272 x g	2,272 x g	2,272 x g	
M10 rotor	75775706					2,576 x g
Standard microplate carriers for M10 rotor ⁴	75775723					2,576 x g
MicroClick 18 x 5 rotor	75775765					22,351 x g

⁴ Rotor sold separately.

Add-on centrifuges

Thermo Scientific centrifuge	Includes	Cat. No.	Max speed	Max RCF
Sorvall Legend Micro 21R refrigerated microcentrifuge	24 x 1.5/2.0 mL rotor with ClickSeal biocontainment lid	75772446	14,800 rpm	21,100 x g
Sorvall Legend Micro 21 ventilated microcentrifuge	24 x 1.5/2.0 mL rotor with ClickSeal biocontainment lid	75772436	14,800 rpm	21,100 x g
Sorvall Legend Micro 21R refrigerated microcentrifuge	Dual row 18 x 2.0/0.5 mL rotor with screw-on lid	75772559	14,800 rpm	20,800 x g
Sorvall Legend Micro 21 ventilated microcentrifuge	Dual row 18 x 2.0/0.5 mL rotor with screw-on lid	75772558	14,800 rpm	20,800 x g
mySPIN 12 mini centrifuge	<ul style="list-style-type: none"> 12 x 1.5/2.0 mL tube rotor 32 x 0.2 mL tube rotor (singles or 4 x 8 strip) 0.2 mL and 0.5 mL tube adapters (sets of 12) 	75774081	12,500 rpm	9,800 x g
mySPIN 6 mini centrifuge	<ul style="list-style-type: none"> 6 x 1.5/2.0 mL tube rotor 16 x 0.2 mL tube rotor (singles or 2 x 8 strip) 0.2 mL and 0.5 mL tube adapters (sets of 6) 	75774061	6,000 rpm	2,000 x g

Valid while supplies last. All promotions valid for orders placed between July 1, 2017 and December 31, 2017 by residents of the United States and Canada. Packages and discounted add-on products must appear on same order to receive discount. "Savings" or "Discount" indicated in any promotion herein represent the maximum percentage difference between the aggregate price for individual purchase of each item contained in the promotional package at the current standard MSRP and the MSRP for the promotional price for each promotional package. Valid only in connection with purchase of promotional packages identified herein using the part numbers listed. All pricing information and values based on current list prices. All offers subject to Thermo Fisher standard terms and conditions of sale, and Thermo Fisher makes no additional warranties, express or implied, in connection with promotional products. Promotional products will be shipped with purchased products. Please see www.thermofisher.com/spinitwarranty for complete warranty offer and coverage details. Not valid in connection with any other offer or discount. Void where prohibited by law or company policy. See representative for additional information. Please note that the value of the specific offer(s) the customer may receive from the manufacturer under this program is a "discount or other reduction in price" to the customer under section 1128B(b)(3)(A) of the Social Security Act [42 U.S.C. 1320a-7b (b)(3)(a)]. Accordingly, the customer shall disclose this and any other discounts or other reduction in price received under this program under any state or federal program which provides cost or charge-based reimbursements to the customer for the products or services purchased under this program.

Find out more at thermofisher.com/spinit



To enhance your cell culture performance

More scientists worldwide trust their valuable cultures to Thermo Scientific CO₂ incubators than any other brand. They depend on proven reliability, exceptional contamination prevention and optimal growing conditions. Delivered with innovative features like HEPA air filtration that surrounds cells with clean roomlike air quality and a choice of 100% pure copper or polished stainless steel interior surfaces. Plus a high-temperature decontamination function that eliminates the need for autoclaving and handling components. The inside story is simple: our CO₂ incubators let you culture with complete confidence. Day after day. Year after year.

Find out more at thermofisher.com/co2



In the United States:

For customer service, call 1-800-766-7000
To fax an order, use 1-800-926-1166
To order online: fishersci.com

In Canada:

For customer service, call 1-800-234-7437
To fax an order, use 1-800-463-2996
To order online: fishersci.ca

ThermoFisher
SCIENTIFIC