

## BMP®21-LAB Label Printer

www.fishersci.com

Where  
Pens Fail.  
Printers  
Succeed.

When it comes to in-the-lab labeling, illegible or smeared writing is not an option. With the powerful and affordable BMP®21-LAB printer on hand, you can rely on crisp, long-lasting identification. Once you experience the built-in symbols, durable labels and vial/tube auto-sizing capabilities of the BMP21-LAB printer, you'll never use a pen again.

### Labels Tested for Labs

- Labels and inks built to withstand harsh lab environments, including autoclaves, freezers, liquid nitrogen, and isopropyl alcohol and methyl ethyl ketone chemicals
- Unlike handwritten identification, printed labels reduce errors with easy-to-read text that fits more information in a small space
- Labels engineered for the lab means you never lose your data due to a failed label
- Technical Data Sheets (TDS) available with the specific properties and test results of each material, available at [BradyID.com/techdata](http://BradyID.com/techdata)

### Convenient Printer Features

- Vial label shortcut key automatically cuts labels to fit to vial and tube sizes
- Greek symbols and time and date stamps for enhanced sample tracking
- Built-in serialization and bar code symbologies provide more information in a smaller footprint
- Drop-lock-and-print cartridges for quick printing with no setup required
- Easy to use and easy to train others to use
- Variety of power options (use AA batteries, rechargeable battery or AC power supply — all sold separately)

### Easy to Own and Maintain

- Label supplies and printer available through top lab distributors
- Low price point allows each technician or lab station to have a printer
- Technical support for the life of the product
- Two-year warranty to ensure it remains in top working condition



### BMP®21-LAB Printer

Fisher Scientific Cat #	Description
19102824	BMP21-LAB Printer Blister Pack

*Ships with:  
Printer + Lanyard +  
M21-750-7425 label  
cartridge*

### BMP®21-LAB & Battery Pack Kit

Fisher Scientific Cat #	Description
19102825	BMP21-LAB Printer Kit

*Ships with: Printer +  
Li-ion Battery + Charger/  
Power Cord + Lanyard  
+ M21-750-7425 label  
cartridge*

## Label Materials that Last


### Ultra-thin Polyester (B-461)



- Ultra-thin label easily slides in and out of racks and centrifuges
- Ideal for tubes, vials and conicals
- Lasts in liquid nitrogen, autoclaves and hot water baths

Fisher Scientific Cat #	Color	Width Inch (mm)	Length Ft (m)
19102718	Black on White	0.375 (9.53)	21 ft (6.40 m)
19102731	Black on White	0.500 (12.70)	21 ft (6.40 m)
19102744	Black on White	0.750 (19.05)	21 ft (6.40 m)

### Polypropylene Label (B-7425)

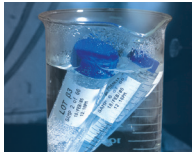

- Versatile, durable and economical
- Ideal for vials, tubes and other specimen containers
- Lasts in liquid nitrogen

Fisher Scientific Cat #	Color	Width Inch (mm)	Length Ft (m)
19140448	Black on White	0.375 (9.53)	21 ft (6.40 m)
19140449	Black on White	0.500 (12.70)	21 ft (6.40 m)
19140450	Black on White	0.750 (19.05)	21 ft (6.40 m)

### Chemical-resistant Polyester Label (B-488)



- Ideal for slides
- Lasts in freezers and autoclaves, and withstands DMSO, ethanol and short-term xylene exposure

Fisher Scientific Cat #	Color	Width Inch (mm)	Length Ft (m)
19102719	Black on White	0.375 (9.53)	21 ft (6.40 m)
19102732	Black on White	0.500 (12.70)	21 ft (6.40 m)
19102745	Black on White	0.750 (19.05)	21 ft (6.40 m)

### Nylon Cloth Label (B-499)



- Easy-to-handle label for non-rigid and curved surfaces
- Ideal for bags, bottles and tubes
- Lasts in liquid nitrogen, freezers and autoclaves

Fisher Scientific Cat #	Color	Width Inch (mm)	Length Ft (m)
19102720	Black on White	0.375 (9.53)	16 ft (4.88 m)
19102733	Black on White	0.500 (12.70)	16 ft (4.88 m)
19102746	Black on White	0.750 (19.05)	16 ft (4.88 m)

### Clear Polyester Material (B-430)



- For flat or large curved surfaces
- Ideal for general purpose bottles, flasks and dishes
- Lasts in freezers and autoclaves

Fisher Scientific Cat #	Color	Width Inch (mm)	Length Ft (m)
19102805	* Black on Clear	0.250 (6.35)	21 ft (6.40 m)
19102806	* White on Clear	0.250 (6.35)	21 ft (6.40 m)
19102717	Black on Clear	0.375 (9.53)	21 ft (6.40 m)
19102807	White on Clear	0.375 (9.53)	21 ft (6.40 m)
19102730	Black on Clear	0.500 (12.70)	21 ft (6.40 m)
19102808	White on Clear	0.500 (12.70)	21 ft (6.40 m)
19102743	Black on Clear	0.750 (19.05)	21 ft (6.40 m)
19102809	White on Clear	0.750 (19.05)	21 ft (6.40 m)

\* Cartridge is only compatible with the BMP@21-LAB printer.

### Durable Vinyl Material (B-595)



- Ideal for equipment, shelves, cabinets and general facility ID
- Available in a variety of colors
- For uneven and rough surfaces

Fisher Scientific Cat #	Color	Width Inch (mm)	Length Ft (m)
19102810	* Black on White	0.250 (6.35)	21 ft (6.40 m)
19102833	Black on White	0.375 (9.53)	21 ft (6.40 m)
19102834	Black on White	0.500 (12.70)	21 ft (6.40 m)
19102781	Black on White	0.750 (19.05)	21 ft (6.40 m)
19102811	* Black on Yellow	0.250 (6.35)	21 ft (6.40 m)
19102843	Black on Yellow	0.375 (9.53)	21 ft (6.40 m)
19102835	Black on Yellow	0.500 (12.70)	21 ft (6.40 m)
19102851	Black on Yellow	0.750 (19.05)	21 ft (6.40 m)
19102841	Black on Orange	0.375 (9.53)	21 ft (6.40 m)
19102846	Black on Orange	0.500 (12.70)	21 ft (6.40 m)
19102849	Black on Orange	0.750 (19.05)	21 ft (6.40 m)
19102812	White on Black	0.375 (9.53)	21 ft (6.40 m)
19102816	White on Black	0.500 (12.70)	21 ft (6.40 m)
19102820	White on Black	0.750 (19.05)	21 ft (6.40 m)
19102842	White on Red	0.375 (9.53)	21 ft (6.40 m)
19102847	White on Red	0.500 (12.70)	21 ft (6.40 m)
19102850	White on Red	0.750 (19.05)	21 ft (6.40 m)
19102839	White on Blue	0.375 (9.53)	21 ft (6.40 m)
19102844	White on Blue	0.500 (12.70)	21 ft (6.40 m)
19102780	White on Blue	0.750 (19.05)	21 ft (6.40 m)
19102813	White on Brown	0.375 (9.53)	21 ft (6.40 m)
19102817	White on Brown	0.500 (12.70)	21 ft (6.40 m)
19102821	White on Brown	0.750 (19.05)	21 ft (6.40 m)
19102840	White on Green	0.375 (9.53)	21 ft (6.40 m)
19102845	White on Green	0.500 (12.70)	21 ft (6.40 m)
19102848	White on Green	0.750 (19.05)	21 ft (6.40 m)
19102815	White on Purple	0.375 (9.53)	21 ft (6.40 m)
19102819	White on Purple	0.500 (12.70)	21 ft (6.40 m)
19102823	White on Purple	0.750 (19.05)	21 ft (6.40 m)
19102814	Black on Grey	0.375 (9.53)	21 ft (6.40 m)
19102818	Black on Grey	0.500 (12.70)	21 ft (6.40 m)
19102822	Black on Grey	0.750 (19.05)	21 ft (6.40 m)

\* Cartridge is only compatible with the BMP@21-LAB printer.

BN#0618155

© 2015 Brady Worldwide Inc. ALL RIGHTS RESERVED

#### In the United States:

For customer service, call 1-800-766-7000

To fax an order, use 1-800-926-1166

To order online: [www.fishersci.com](http://www.fishersci.com)

#### In Canada:

For customer service, call 1-800-234-7437

To fax an order, use 1-800-463-2996

To order online: [www.fishersci.ca](http://www.fishersci.ca)



A Thermo Fisher Scientific Brand